



Product sheet  
RLED 2.0

#### Features

- Two independent channels
- Simple calibration process enables support for almost all LED bulbs on the market
- Maximum output current: 1200 VA (230/115 VAC)
- Auto/Manual/Off mode for each channel

#### Benefits

- Lights can be dimmed to extremely low levels of light intensity
- High level of stability extends bulb life
- Simple calibration process enables supporting a wide variety of bulbs
- Automatic and manual brightness control provides lighting only when required
- Key hole mounting simplifies installation
- Rugged terminals, water tight seals for power cables meet rigorous poultry house conditions

## RLED 2.0

### Light Dimmer for Energy Saving Lamps

RLED 2.0 provides simple, effective control over the majority of LED lighting systems used in the poultry industry. Along with the RLED 2.0's advanced electronic circuits, the Light Dimmer's software package provides superior performance and functionality, enabling high caliber, stable dimming capability. The RLED 2.0 can be managed directly by a poultry house controller via 0-10 volt analog output or communication line.




Rled 2.0



# Up to 10 independent channels

in Platinum Layers mode. Other modes support up to 4 channels.

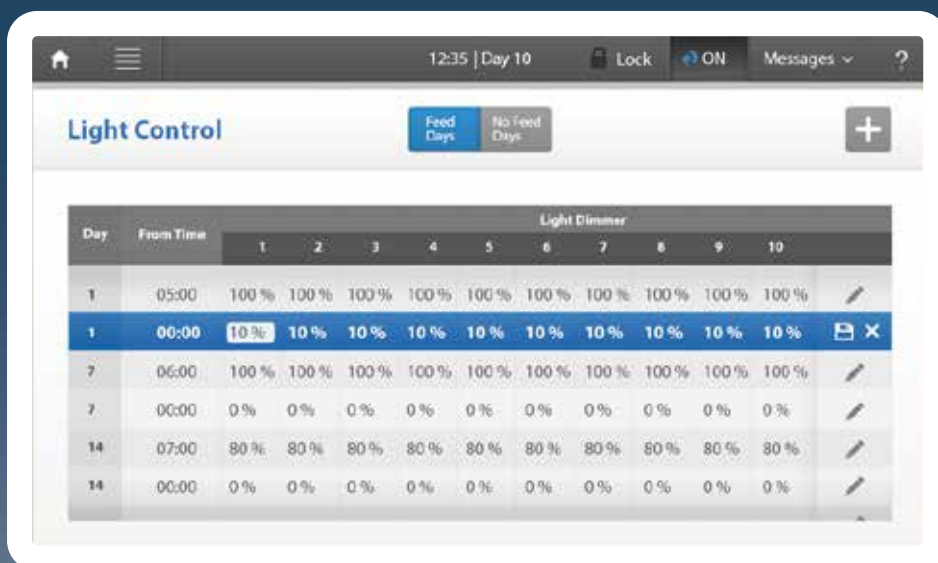

Platinum Touch



**Australia** Phone +61 2 8843 1594, [agh.info@munters.com.au](mailto:agh.info@munters.com.au), **Brazil** Phone +55 41 3317 5050, [contato@munters.com](mailto:contato@munters.com), **Canada** Phone +1 517 676 7070, [aghort.info@munters.com](mailto:aghort.info@munters.com), **China** Phone +86 10 8048 3493, [marketing@munters.cn](mailto:marketing@munters.cn), **Denmark** Phone +45 98 623 311, [aghort@munters.dk](mailto:aghort@munters.dk), **Germany** +49 (0) 25 58 - 93 92-0, **India** Phone +91 20 6681 8900, [info@munters.in](mailto:info@munters.in), **Indonesia** Phone +66 2 642 2670, [info@munters.co.th](mailto:info@munters.co.th), **Israel** Phone +972 3 920 6200, [info@munters.co.il](mailto:info@munters.co.il), **Italy** Phone +39 0183 5211, [info@munters.it](mailto:info@munters.it), **Japan** Phone +81 3 5970 0021, [mkk@munters.jp](mailto:mkk@munters.jp), **Korea** Phone +82 2 7618 701, [munters@munters.co.kr](mailto:munters@munters.co.kr), **Mexico** Phone +52 818 2625 400, [dinfo@munters.com](mailto:dinfo@munters.com), **Singapore** Phone +65 7 446 828, [info@munters.com.sg](mailto:info@munters.com.sg), **South Africa and Sub-Sahara Countries** Phone +27 11 997 2000, [info@munters.co.za](mailto:info@munters.co.za), **Spain** Phone +39 0183 5211, [info@munters.it](mailto:info@munters.it), **Sweden** Phone +46 8 6266 300, [info@munters.se](mailto:info@munters.se), **Thailand** Phone +66 2 6422 670, [info@munters.co.th](mailto:info@munters.co.th), **Turkey** Phone +90 262 7513 750, [info@muntersform.com](mailto:info@muntersform.com), **USA** Phone +1 517 676 7070, [aghort.info@munters.com](mailto:aghort.info@munters.com), **Export & Other countries** Phone +39 0183 5211, [info@munters.it](mailto:info@munters.it)

Your closest distributor