


VX 14" - 26"

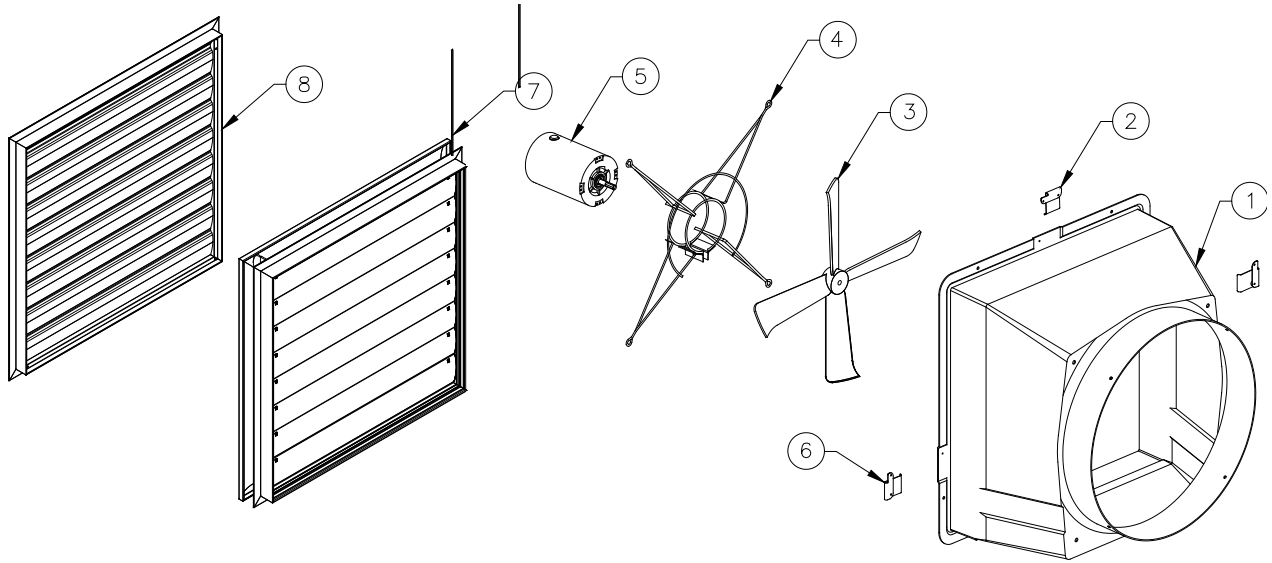

Item	Catalog No.	Description	Qty.
1	FH3414	Housing, 14" Vortex Fan, with Clips & Labels, FG	1
	FH3416	Housing, 16" Vortex Fan, with Clips & Labels, FG	1
	FH3418	Housing, 18" Vortex Fan, with Clips & Labels, FG	1
	FH3424	Housing, 24" Vortex Fan, with Clips & Labels, FG	1
	FH3127	Housing, 26" Vortex Fan, with Clips & Labels, FG	1
2	FH2119	Right Shutter Clip, AL	2
3	FP1031SS	Propeller, 14"DD, 7-Blade, ½" Bore, Set Screws, AL	1
	FP1038SS	Propeller, 16"DD, 4-Blade, Set Screws, AL	1
	FP1008SS	Propeller, 18"DD, 5-Blade, ½" Bore, Set Screws, AL	1
	FP1033SS	Propeller, 24"DD, 4-Blade, ½" Bore, Set Screws, AL	1
	FP1126SS	Propeller, 26.5" DD, 3-Blade, Set Screws, AL	1
4	FH1008	14" Fan, Motor Mount, PVC Coated	1
	FH1009	16"/18" Fan, Motor Mount, PVC Coated	1
	FH1010	24" Fan, motor Mount, PVC Coated	1
	FH2526	26" Fan, Motor Mount, PVC Coated	1
5	FM1010	14" DD, Motor, ⅛ HP, 1625 RPM, 48 Fr., 1 ph., 115/230V	1
	FM1043	16" DD, Motor, ¼ HP, 1625 RPM, 48 Fr., 1 ph., 115/230V	1
	FM1009	18" DD, Motor, ⅓ HP, 1625 RPM, 48 Fr., 1 ph., 115/230V	1
	FM1008	24"/26" DD, Motor, ⅓ HP, 1075 RPM, 48 Fr., 1 ph., 115/230V	1
	FM1070	24"/26" DD, Motor, ⅓ HP, 1075 RPM, 48 Fr., 3 ph., 208-230/460V	1
6	FH2117	Left Shutter Clip, Al (14"-26" fans only)	1
7	PT0914	Shutter, 16¾" SQ., Belted inlet, White Plastic	1
	PT1618	Shutter, 21⅝" SQ., Belted inlet, White Plastic	1
	PT24	Shutter, 27⅝" SQ., Belted inlet, White Plastic	1
	PT26	Shutter, 29.4" SQ., Belted inlet, White Plastic	1
8	PZ0914	Shutter, 16¾" SQ., White Plastic	1
	PZ1618	Shutter, 21⅝" SQ., White Plastic	1
	PZ24	Shutter, 27⅝" SQ., White Plastic	1
	PV26	Shutter, 29.4" SQ., White Plastic	1