



ATLAS 74

Big Performance

The Munters Atlas fan offers big performance, for a comfortable, healthy herd.

Features


- The most efficient fan in its class measuring 22.4 cfm/watt under typical operating conditions at a static pressure of 0.10"
- Highest airflow of any fan in its class with 50,400 cfm at 0.10" SP
- Calculate your true dollar savings over other models with our state-of-the-art Total Cost of Ownership comparison tool
- Durable fiberglass housing for a lifetime of use
- Robust 182-frame-premium-motor to ensure top performance and longevity
- Available in two versions for delivering optimum ventilation: Premium and Efficient models
- May qualify for energy rebates with an impressive 22.4 cfm/watt at 0.10" SP in the Efficient model

We believe longevity and value are two of the most important factors when purchasing your ventilation systems. Not only does Munters offers you the best performing fans on the market, we also have years of experience when it comes to the entire process from ventilation design to post installation follow up. Munters will be there throughout the process to ensure your operation is running at peak performance.

The Atlas 74 is designed, engineered and built in the USA with premium American-made parts for the demanding conditions of a modern dairy operation. Featuring a corrosion-resistant fiberglass housing that is easy to clean and built to withstand tough conditions. Munters also uses a premium 182-frame-motor to give you a more durable and top performing motor for years of use. The fan is designed to operate comfortably within the limits of the motor's range, not at the upper limits where over usage can degrade the motor performance prematurely.

Two options are available for a customized approach to ventilation: Atlas Premium which provides the best balance between airflow and efficiency in its class. Atlas Efficient is the most energy efficient at 22.4 cfm/watt under typical operating conditions at a static pressure of 0.10" qualifying it under many energy rebate programs.

Atlas is designed to provide the best airflow and no other fan of this size performs better, meaning fewer fans to install and maintain and a lower total cost of ownership. Ask for our Total Cost of Ownership calculation tool and you will see for yourself that Munters is the best value when it comes to your dairy operation.

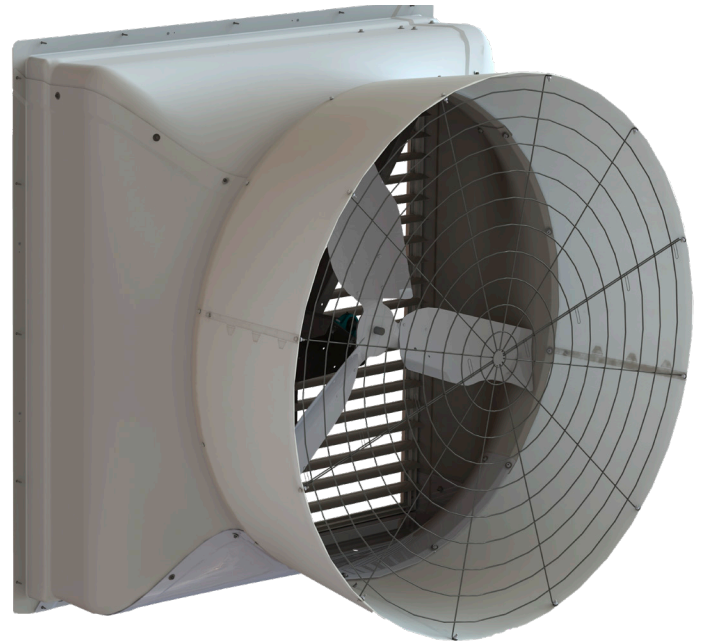

ATLAS 74

Exhaust Fan

Technical specifications

Dimensions

Fan Diameter	74"
A	5½"
B	21½"
C	44½"
D	89"
E	89"
F	13⅞"
G	35¾"
H	60⅜"
J	2⅝"
K - Diameter	85⅜"
Wall Opening	85"Wx85"H

Measurement diagram for reference only.

Performance[◇]

Static Pressure	Atlas 74 - Premium		Atlas 74 - Efficient	
	CFM	CFM/WATT	CFM	CFM/WATT
0.00"	57,700	27.5	54,900	29.3
0.05"	54,100	24.1	51,200	25.6
0.10"	50,400	21.2	47,400	22.4
0.15"	46,500	18.7	43,100	19.4
0.20"	42,100	16.2	38,200	16.5
Airflow Ratio	0.78		0.75	

[◇]Tested in accordance with AMCA Standard 210

